


Rollers & Conveyor Components

Rollers & Conveyor Components

Product Name	TM Magnetic Transmission Drive Parts for Non-contact Magnetic Force Transmission	-Economy Type-	-Straight / Crowned Type-	-Tapped Straight / Crowned Type-	Vertical Guide Rollers
Page	996	996	997	999	1000

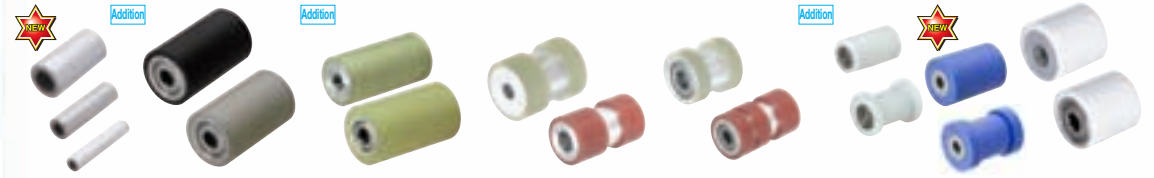

Rollers with Oil Free Bushing	-Bearing Type-	-Urethane Thickness Selectable Type-	Groove Rollers	-Bearing Type-	Plastic Rollers
1000	1001	1003	1004	1004	1005



-Set Screw Hole Type-	-Press-Fit Straight Type-	-Press-Fit Bearing Type-	Aluminum Rollers	Pipe Rollers-Straight Type-	-Bearing Type-	-Set Screw Type-
1006	1007	1008	1008	1009	1010	1011



Long Hollow Rollers	With Keyway	-With Keyway / Tapped Type-	Pipe Rollers with Shafts	Urethane Rollers with Collars	Knurled Urethane Rollers-Set Screw Hole on One End-	Bearing Type
1012	1013	1013	1014	1015	1015	1016



-Set Screw Type-	Knurled Urethane Rollers	With Shafts	-Both Ends Threaded Type-	-Urethane Thickness Configurable Type-	Silicon Rubber / Urethane Mold Bearings	-Crown Type-
1016	1016	1017	1017	1018	1019	1020



-Threaded Flat Type-	-Threaded Crown Type-	- Inner Wheel Protruded Type-	Threaded Bearings	Shafts for Urethane Mold Bearings	Eccentric Bushings	Engineered Plastic Bearings - Antistatic Type-	-Flat Type-
1021	1022	1023	1024	1024	1024	1025	1025



Engineered Plastic Bearings -Crown Type- With Brackets -Flat Type-	-Crown Type-	Engineered Plastic Bearings -U Groove Type-	-V Groove Type-	-One Side Flanged Type-
1025	1026	1026	1026	1026



Guide Rollers -V Groove 60° Type / V Groove 90° Type / Sheaves (For Wire Cables) / Flat Type / Double Flanged Type-	Motor Rollers	Conveyor Rollers	Conveyor Rollers -Sprockets Attached Type-	Plastic Conveyor Rollers
1027 / 1028	1030	1031	1032	1032



Conveyor Roller Shafts	Mini-Rollers for Conveyors	Conveyor Wheels	Rubber Lined Conveyor Wheels	Roller Carriers-Roller Width 7 - 9 / 15 / 25mm Type Milled / Pressed-	-With Brackets-
1033	1033	1034	1034	1035-1037	1035-1038



-Roller Width 50mm Type-	Roller Conveyors -Roller Dia. 19mm Type-	-Roller Dia. 28mm Type-	-Roller Dia. 38mm Type-	Ball Rollers -Hexagon Bolt Type-	-Press-Fit Type-
1038	1040	1041	1042	1043	1043



-Insertion / Adhesion Type-	Plunger-equipped Ball Roller -Press-Fit Type-	-Threaded Type-	Ball Roller Lock Nut -Flanged Type-	-Set Screw Type-	-Round Bolt Type-	Ball Roller Units
1043	1043	1043	1044	1044	1044	1045



-Ball Roller - Milled Steel Type-	-Steel Press Formed Type-	UHMW Guide Rails
1046	1046	1047



UHMW Guide Rail Shields	Side Tapes / High Bond Double -Sided Tapes	Guide Rails	Stainless Steel Sliding Plates	Product Chute Thin Plates
1049	1050	1050	1051	1051