


BOTH VALVES SP COUPLING

—SOCKET • PLUG— ~HEAT RESISTANT 180°C~


Compatible with MISUMI SP coupler for double valve cooling.

Sockets

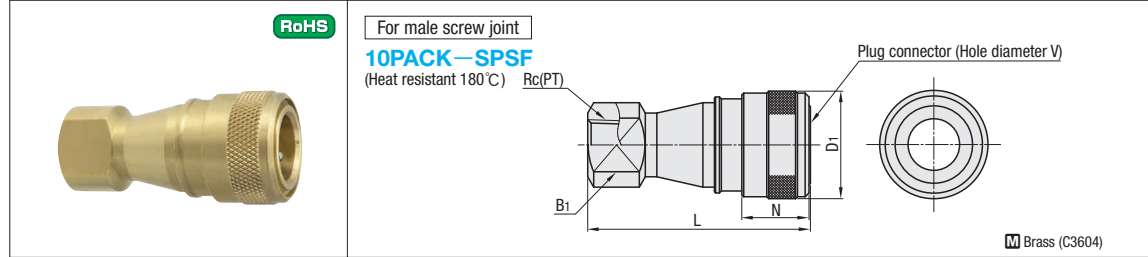


Matching Plug	Plug connection parts			L	Dihedral side B1	Taper female thread Rc(PT)	Part Number		U/Price 10PACKS
	Hole diameter (V)	N	D1				Type	No.	
• SP coupling • SP coupler Tip diameter V=14	14	17.5	28	58	17	1/4	10PACK—SPSF	2	Quotation
• SP coupling • SP coupler Tip diameter V=19	19	20	35	65	21	3/8		3	

Plugs

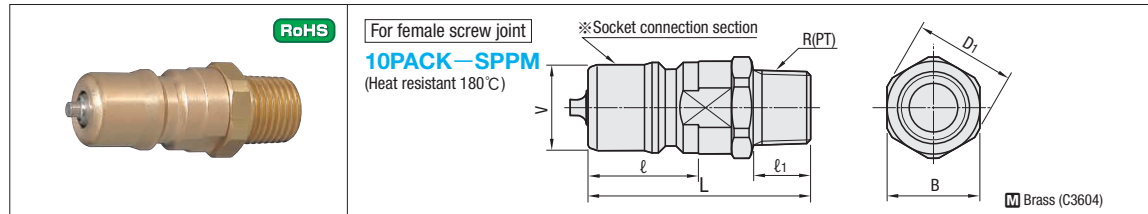

Matching socket	Socket connection section		L	D1	Allen side B	Tapered male thread R(PT)	l1	Part Number		U/Price 10PACKS
	Hole diameter (V)	l						Type	No.	
• SP coupling • SP coupler Tip diameter V=14	14	22	43.5	18.5	17	1/4	12	10PACK—SPPM	2	Quotation
• SP coupling • SP coupler Tip diameter V=19	19	25.2	50.4	23	21	3/8	13		3	

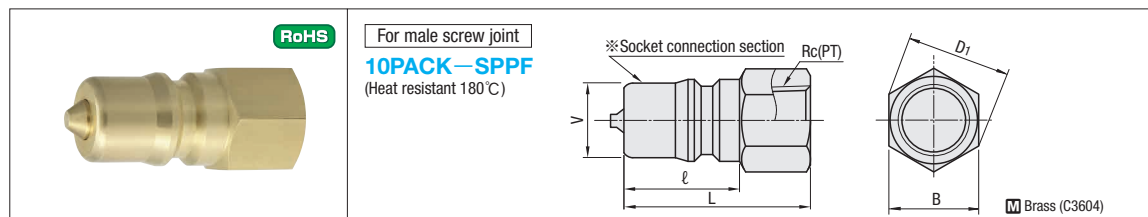

Matching socket	Socket connection section		L	D1	Allen side B	Taper female thread Rc(PT)	Part Number		U/Price 10PACK
	Hole diameter (V)	l					Type	No.	
• SP coupling • SP coupler Tip diameter V=14	14	22	35.5	18.5	17	1/4	10PACK—SPPF	2	Quotation
• SP coupling • SP coupler Tip diameter V=19	19	25.2	39.9	23	21	3/8		3	

- Use in atmospheric pressure 980kPa (10kgf/cm²) or lower.
- Heat resistance is 180°C, and it can be used for both water and oil.
- For SP coupling, there are automatic open/close valves in socket and plug respectively due to the structure of double valves.

Order **Part Number**
10PACK—SPSF2

Days to Ship

Quotation


BOTH VALVES SP COUPLING

—STAINLESS SOCKET • PLUG— ~HEAT RESISTANT 180°C~

Compatible with MISUMI SP coupler for double valve cooling.


Non JIS material definition is listed on P.1351 - 1352

Sockets

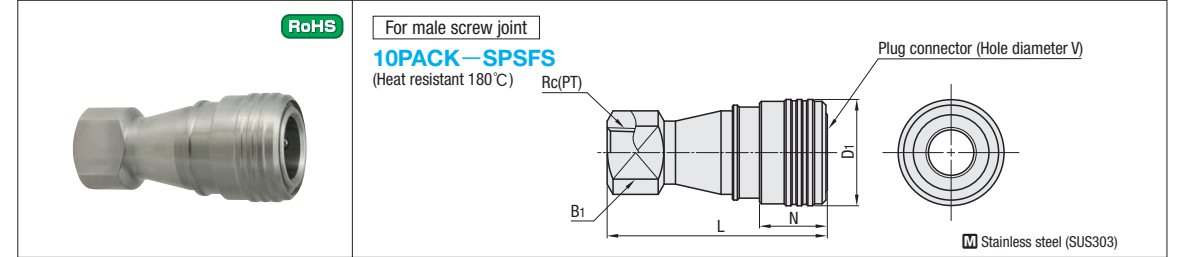


Matching Plug	Plug connection parts			L	Dihedral side B1	Tapered female screw Rc(PT)	Part Number		U/Price 10PACKS
	Hole diameter (V)	N	D1				Type	No.	
• SP coupling • SP coupler Tip diameter V=14	14	17.5	28	58	17	1/4	10PACK—SPSFS	2	Quotation
• SP coupling • SP coupler Tip diameter V=19	19	20	35	65	21	3/8		3	

Plugs

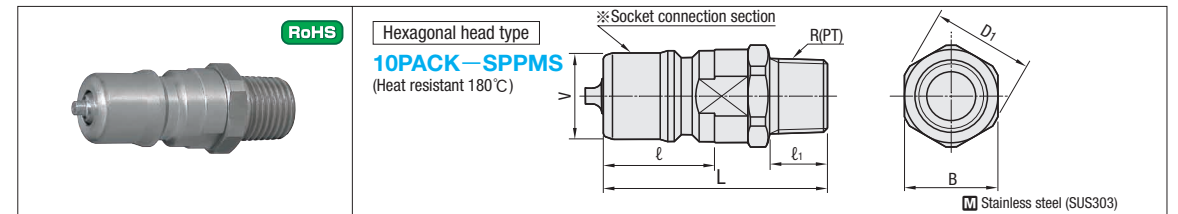

Matching socket	Socket connection section		L	D1	Allen side B	Tapered male thread R(PT)	l1	Part Number		U/Price 10PACKS
	V	l						Type	No.	
• SP coupling • SP coupler Tip diameter V=14	14	22	43.5	18.5	17	1/4	12	10PACK—SPPMS	2	Quotation
• SP coupling • SP coupler Tip diameter V=19	19	25.2	50.4	23	21	3/8	13		3	

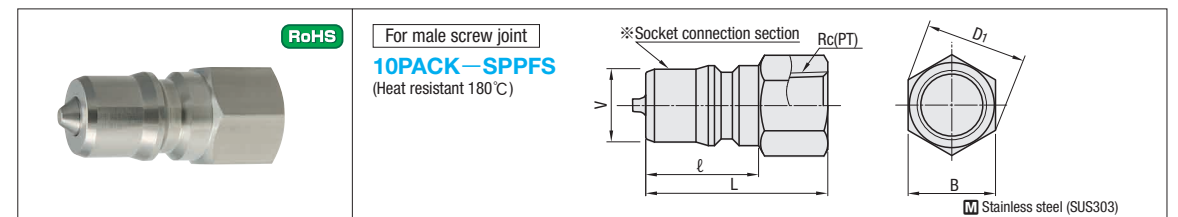

Matching socket	Socket connection section		L	D1	Allen side B	Tapered female screw Rc(PT)	Part Number		U/Price 10PACKS
	V	l					Type	No.	
• SP coupling • SP coupler Tip diameter V=14	14	22	35.5	18.5	17	1/4	10PACK—SPPFS	2	Quotation
• SP coupling • SP coupler Tip diameter V=19	19	25.2	39.9	23	21	3/8		3	

- Use in atmospheric pressure 980kPa (10kgf/cm²) or lower.
- Heat resistance is 180°C, and it can be used for both water and oil.
- For SP coupling, there are automatic open/close valves in socket and plug respectively due to the structure of double valves.
- These stainless products resist rust.

Order **Part Number**
10PACK—SPSFS2

Days to Ship

Quotation